

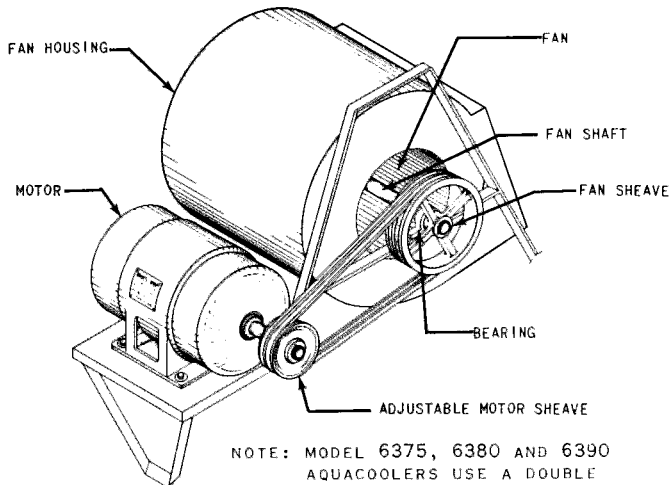


AQUACOOLER PARTS LIST
for
Models 6305, 6308, 6310, 6315, 6320, 6325, 6330, 6340, 6350,
6360, 6375, 6380 and 6390

(SEE ITEMIZED PARTS LIST ON REVERSE SIDE)

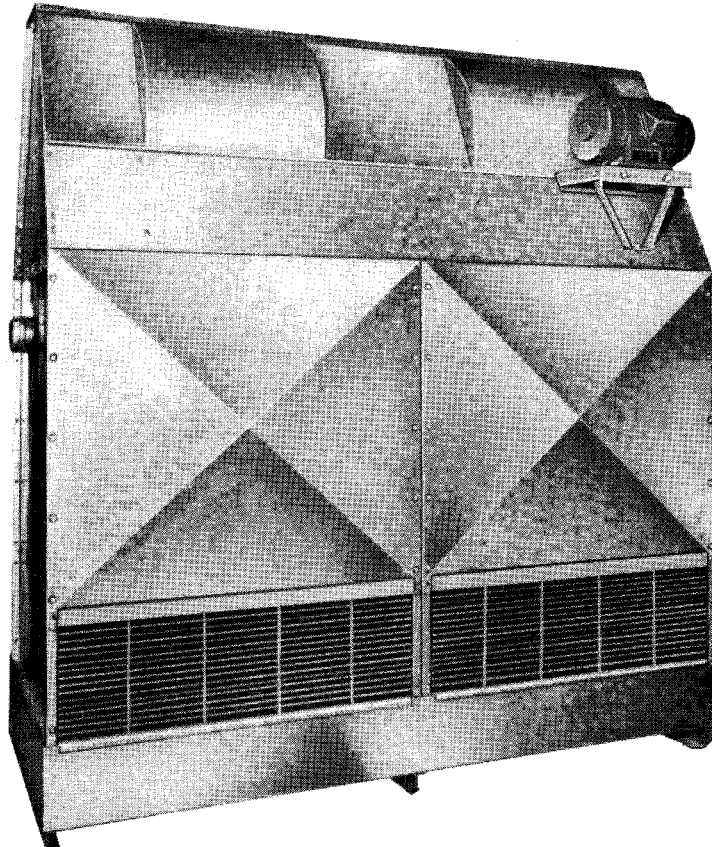

NOTE: MODEL 6375, 6380 AND 6390
AQUACOOLERS USE A DOUBLE
SHAFT MOTOR AND DUAL DRIVES

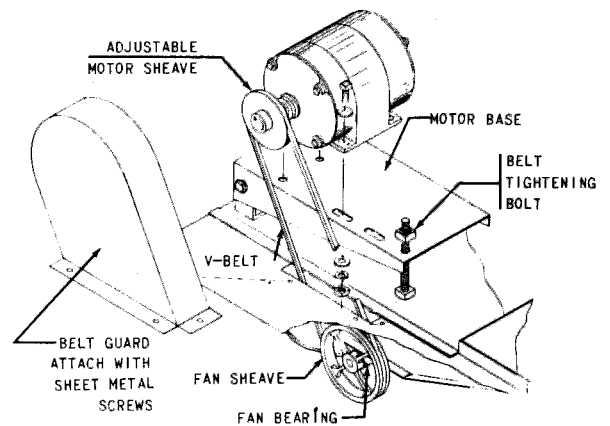

IMPORTANT -- The SERIAL and MODEL NUMBERS of tower MUST be provided when ordering parts.

AQUACOOLER PARTS LIST

REF. NO.	DESCRIPTION OF PARTS	MODELS - Quantities Used												
		6305	6308	6310	6315	6320	6325	6330	6340	6350	6360	6375	6380	6390
1	MOTOR													
	½ Hp, 1725 RPM TE	1												
	¾ Hp, 1725 RPM TEFC		1	1										
	1-½ Hp, 1750 RPM Protected				1	1								
	2 Hp, 1750 RPM Protected						1							
	3 Hp, 1750 RPM Protected							1	1					
	5 Hp, 1750 RPM Protected									1	1			
	7-½ Hp, 1750 RPM Protected, Double Extended Shaft											1		
10 Hp, 1750 RPM Protected, Double Extended Shaft												1		
15 Hp, 1750 RPM Protected, Double Extended Shaft													1	
2	MOTOR SHEAVES													
	Browning 1VP-40, 5/8" Bore	1												
	Browning 1VP-50, 5/8" Bore		1											
	Browning 1VP-44, 5/8" Bore			1										
	Browning 1VP-56, 7/8" Bore				1	1	1							
	Browning 2VP-56, 1-1/8" Bore							1	1	1				
	Browning 2VP-62, 1-1/8" Bore										1			
	Browning 2VP-60A, 1-3/8" Bore											2		
	Browning 2VP-75A, 1-3/8" Bore												2	
	Browning 2V68 B80P, 1-5/8" Bore													2
3	FAN SHEAVES													
	Browning AK-69H, 1" Bore	1												
	Browning AK-79H, 1" Bore		1											
	Browning 1TB-80, 1-11/16" Bore			1										
	Browning 1TB-90, 1-11/16" Bore				1									
	Browning 1TB-136, Q1 Bushing, 1-11/16" Bore					1	1							
	Browning 2TB-136, Q1 Bushing, 1-11/16" Bore							1						
	Browning 2TB-136, Q1 Bushing 2" Bore								1	1				
	Browning 2TB-184, Q1 Bushing 2" Bore										1			
	Browning 2TB-154, Q1 Bushing, 1-11/16" Bore											2		
	Browning 2TB-184, Q1 Bushing, 1-11/16" Bore												2	2
4	V-BELTS													
	Browning A-48	1												
	Browning A-53		1											
	Browning A-51			1										
	Browning B-55				1									
	Browning A-71					1								
	Browning B-71						1							
	Browning 2A-75 (Set of 2 matched belts)							1						
	Browning 2B-71 (Set of 2 matched belts)								1					
	Browning 2B-75 (Set of 2 matched belts)									1				
	Browning 2B-85 (Set of 2 matched belts)										1			
	Browning 4B-81 (Set of 4 matched belts)											1		
	Browning 4B-90 (Set of 4 matched belts)												1	1
	5	BEARINGS												
Randall No. PB-NB - G100C108-HE (1" Bore)		2	2											
Randall No. PG-NG - G111F400-HE (1-11/16" Bore)				2	2	2	2							
Randall No. PJ-NJ - G200K500-HE (2" Bore)									2	2	2			
Randall No. QG-MH - G111F408-HE (1-11/16" Bore)											4	4	4	
6	FANS													
	Clarage Type 7/8 Centrifugal, 1" Bore	1												
	Clarage Type 1 Centrifugal, 1" Bore		1											
	Clarage Type 7/8 Centrifugal, 1-11/16" Bore			2										
	Clarage Type 1 Centrifugal, 1-11/16" Bore				2									
	Clarage Type 1-1/2 Centrifugal, 1-11/16" Bore					1	1							
	Clarage Type 1-3/4 Centrifugal, 1-11/16" Bore							1				2	2	2
	Clarage Type 1-1/2 Centrifugal, 2" Bore								2	2				
Clarage Type 1-3/4 Centrifugal, 2" Bore										2				
7	FAN SHAFTS													
	1" Dia. CRS 80842091107	1	1											
	1-11/16" Dia. CRS 80856091261			1	1									
	1-11/16" Dia. CRS 80856091180					1	1	1						
	2" Dia. CRS 80860091343								1	1	1			
1-11/16" Dia. CRS 80856091213											2	2	2	
8	FLOAT VALVES													
	3/8" Flippen	1	1	1	1									
	1/2" Flippen					1	1	1	1	1	1			
	3/4" Flippen											1	1	1