


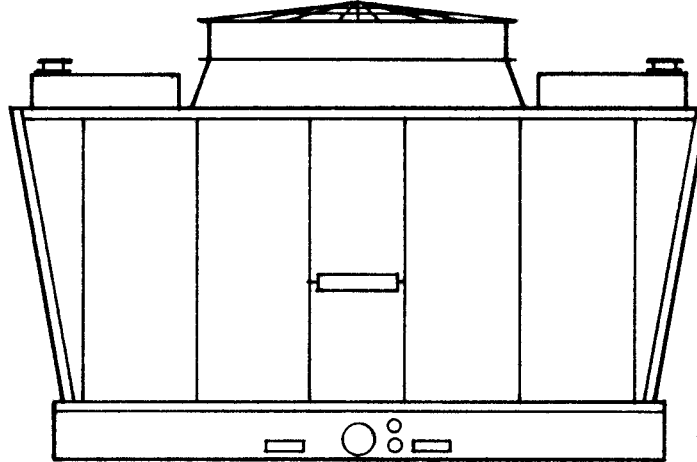

SERIES NC STEEL DOUBLE-FLOW PARTS LIST

for

Models 8601, 8602, 8603, 8604, 8605, 8606, 8607, 8608, 8609, 8610, 8611, 8612, 8613 & 8614



REF. NO.	DESCRIPTION OF PARTS	MODELS – Quantities Used													
		8601	8602	8603	8604	8605	8606	8607	8608	8609	8610	8611	8612	8613	8614
1	MOTOR 5 Hp, 1750 RPM, TEAO Flange Mounted 7-1/2 Hp, 1750 RPM, TEAO Flange Mounted 10 Hp, 1750 RPM, TEAO Flange Mounted 15 Hp, 1750 RPM, TEAO Flange Mounted 20 Hp, 1750 RPM, TEAO Flange Mounted 25 Hp, 1750 RPM, TEAO Flange Mounted	1	1	1	1	1	1	1	1	1	1	1	1	1	1
2	GEAREDUCER Series 11.1*, 2.65/1 Ratio (Fan Shaft Not Tapered) Series 11.1*, 3.20/1 Ratio (Fan Shaft Tapered) * Replaces 11T. Mounting adaptor not required. Series 21.2, 4.105/1 Ratio (Fan Shaft Tapered)	1	1	1	1	1	1	1	1	1	1	1	1	1	1
3a	FAN – TOWERS WITH PVC FILL 54" DIA. H-3-6 72" DIA. H-3-6 72" DIA. H-3-8 84" DIA. H-3-10 84" DIA. H-3-8 96" DIA. H-3-10 96" DIA. H-3-12	1	1	1	1	1	1	1	1	1	1	1	1	1	1
3b	FAN – TOWERS WITH M67 FILL 54" DIA. H-3-6 72" DIA. H-3-6 72" DIA. H-5-4 84" DIA. H-5-4 96" DIA. H-5-4	1	1	1	1	1	1	1	1	1	1	1	1	1	1
4	COUPLING Boston Gear FCBB-20 (Modified) Boston Gear FCBB-25 (Modified) Special Marley 6Q, Close, 15 Hp, 20 Hp Special Marley 6Q, Clost, 25 Hp	1	1	1	1	1	1	1	1	1	1	1	1	1	1
5	FLOAT VALVE ** 1-1/4" DIA., Marley, with Stem and Plastic* Float ** 2-1/2" DIA., Marley, with Stem and Plastic* Float	1	1	1	1	1	1	1	1	1	1	1	1	1	1

* Use Copper Ball Float If Tower Has Cold Water Basin Heater.

** 2-1/2" Float Valve Is Standard On All Multi-Cell Towers Unless Otherwise Specified. Check Float Valve Size Before Ordering.

MANUAL 92-1403